


■スタンダードタイプ



RoHS

Type		材質	S表面処理
H寸選択	H寸指定		
AJKC	AJKB	SS400	四三酸化鉄皮膜 無電解ニッケルメッキ
AJKCM	AJKBM		
AJKCS	—	SUS304	—

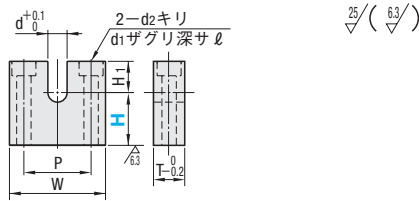


型式		H			d	T	H ₁	P	W	d ₁	d ₂	ℓ	¥基準単価							
Type	No.	選択タイプ		指定タイプ 指定1mm単位									AJKC	AJKCM	AJKCS	AJKB	AJKBM			
(H寸選択) AJKC AJKCM AJKCS (No.3~10)	(H寸指定) AJKB AJKBM	3	10	15	10~40	2.5	7	5	16	26	6	3.5	3.5	700	920	1,370	1,060	1,270		
		4	10	15		20	3.5													
		5	10	15		20	25	4.5	9	6	20	32	8	4.5	4.5	760	1,000	1,480	1,120	1,350
		6	10	15		20	25	5.5								760	1,000	1,480	1,120	1,350
		8	10	15		20	25	7.5	12	8	26	38	9.5	5.5	5.5	880	1,160	1,800	1,240	1,410
		10		15	20	25	9.5	16	10	32	50	14	9	9	1,200	1,590	2,470	1,570	1,940	
		12		15	20	25	11.5	19	11	40	65				1,330	1,770	—	1,710	2,120	
		16			20	25	15.5								1,470	1,950	—	1,850	2,300	

■側面取付タイプ



RoHS

スタンダード		L型		材質	S表面処理
H寸選択	H寸指定	H寸選択	H寸指定		
AJSC	AJSB	AJSLC	AJSCC	SS400	四三酸化鉄皮膜 無電解ニッケルメッキ
AJSCM	AJSBM	AJSLCM	AJSCCM		
AJSCS	—	AJSLCS	AJSCCS	SUS304	—

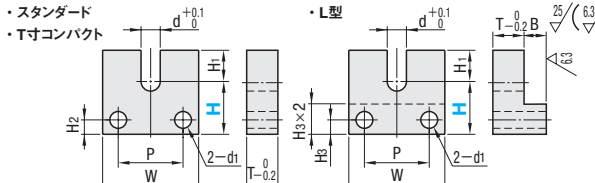

・スタンダード
・T寸コンパクト
・L型
・T寸コンパクト
T寸コンパクトタイプ用の適用アジャストボルトは六角T寸コンパクト(P.1377)になります。

型式			H			d	T		H ₁	H ₂	H ₃	B	P	W							
Type	No.	選択タイプ			指定タイプ 指定1mm単位		スタンダード	コンパクト													
●スタンダード (H寸選択) AJSC AJSCM AJSCS (H寸指定) AJSB AJSBM	●L型 (H寸選択) AJSLC AJSLCM AJSLCS	●T寸コンパクト (H寸選択) AJSCC AJSCCM AJSCCS	3	15	20	10~40	2.5	—	5	4	4	5	16	26							
			4	15	20		3.5	3													
			5	15	20		25	4.5							5						
			6	15	20		25	30								5.5					
			8	20	25		30	40								7.5					
			10	25	30	40	15~80	9.5	16	10	9	7	9	32	50						
			12	25	30	40		11.5	19							11	12	8	10	40	65
			16	25	30	40		15.5													


●T寸コンパクトタイプの場合、W寸は()寸法になります。 ●T寸コンパクトタイプはNo.4~8

■L型タイプ



RoHS

Type		材質	S表面処理
H寸選択	H寸指定		
AJLC	AJLB	SS400	四三酸化鉄皮膜 無電解ニッケルメッキ
AJLCM	AJLBM		

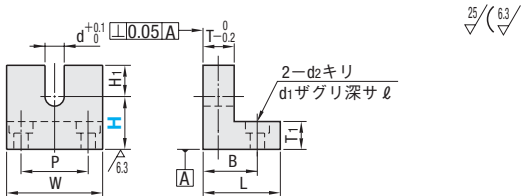

型式		H				d	T	T1	H1	P	L	B	W	d1	d2	ℓ	¥基準単価			
Type	No.	選択タイプ		指定タイプ 指定1mm単位	AJLC												AJLCM	AJLB	AJLBM	
(H寸選択) AJLC AJLCM	3	15	20	16~40	2.5	7	7	5	16	16	11	26	6	3.5	3.5	1,380	1,790	1,880	2,290	
	4	15	20		3.5											1,380	1,790	1,880	2,290	
	5	20	25	21~40	4.5	9	9	6	20	23	16	32	8	4.5	4.5	1,440	1,870	1,940	2,370	
	6	20	25 30		5.5											1,440	1,870	1,940	2,370	
	8	20	25 30		7.5	12	10	8	26	28	20	38	9.5	5.5	5.5	1,670	2,170	2,170	2,670	
(H寸指定) AJLB AJLBM	10		30 35	31~80	9.5	16			10	32	38	27	50			2,340	3,040	2,840	3,540	
	12		30 35		11.5	19	15	11	40	41	30	65	14.0	9	9	2,610	3,390	3,110	3,890	
	16		30 35		15.5											2,930	3,810	3,430	4,310	

	Order 注文例	型式	H		Delivery 出荷日	3 日目発送		ストーク A	500円/1本	P82		Price 価格	数量スライド価格 (※1円未満切り捨て) P81
		AJJC10	20			※無線デジタルメッキ品はストークA適用不可			※同一サイズ3本以上は一律1,350円				

※表示数量を超えてお見積り


・2方向に取り付けることでXYの調整に使用できます。

■スタンダードタイプ



RoHS

Type		材質	S表面処理
H寸選択	H寸指定		
AJKE	AJKB	SS400	四三酸化鉄皮膜 無電解ニッケルメッキ
AJKE	AJKB		
AJKE	—	SUS304	—

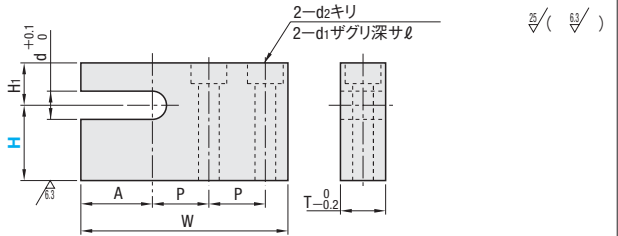


型式														Y基準単価				
Type	No.	H 選択				d	T	H ₁	A	P	W	d ₁	d ₂	ℓ	AJKE	AJKEM	AJKES	
AJKE AJKEM AJKES	4	10	15	20		3.5	7	6	13	9	36	6	3.5	3.5	800	1,020	1,470	
	5	10	15	20	25	4.5	9	7	16	12	46	8	4.5	4.5	860	1,100	1,580	
	6	10	15	20	25	30									5.5	860	1,100	1,580
	8	10	15	20	25	30	7.5	12	12	19	15	55	9.5	5.5	5.5	980	1,260	1,900
	10		15	20	25	30	9.5	16	13	20	21	71	14	9	9	1,300	1,690	2,570

■側面取付タイプ



RoHS

Type		材質	S表面処理
H寸選択	H寸指定		
AJSE	AJSE	SS400	四三酸化鉄皮膜 無電解ニッケルメッキ
AJSE	AJSE		
AJSE	—	SUS304	—

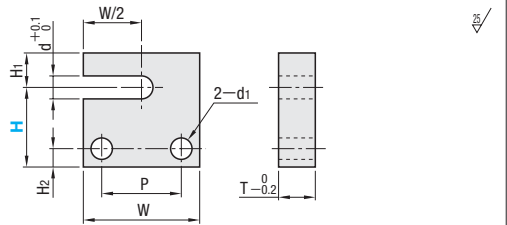

型式		H 選択				d	T	H ₁	H ₂	P	W	d ₁	¥基準単価			
Type	No.												AJSE	AJSEM	AJSSES	
AJSE AJSEM AJSSES	4	15	20			3.5	7	6	4	16	26	4	540	790	1,010	
	5		20	25		4.5	9	7	5	20	32	6	570	820	1,070	
	6		20	25	30	5.5							570	820	1,070	
	8		20	25	30	40	7.5	12	12	6	26	38	7	780	990	1,500
	10				30	40	9.5	16	13	9	32	50	9.5	940	1,200	1,820