



HIGH TORQUE TIMING BELTS -P2M-P3M-P5M-P8M- ハイトルクタイミングベルト (P2M・P3M・P5M・P8M)

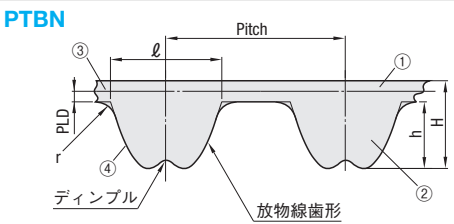

□: 新価格

■ハイトルクタイミングベルトはハイトルクタイミングプーリー P1495~P1500と適合します。

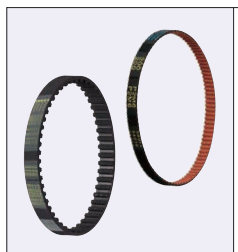

Type	材質						
PTBN	①背ゴム	クロロプレンゴム					
	②歯ゴム	クロロプレンゴム					
	③心線	ガラス繊維					
	④歯布	ナイロン帆布					
種類	Pitch	φ	H	h	PLD	r	単位質量 g/m(幅10mm)
P2M	2	1.30	1.3	0.73	0.254	0.2	14.0
P3M	3	1.95	2.1	1.09	0.381	0.3	22.0
P5M	5	3.25	3.6	1.81	0.571	0.5	41.0
P8M	8	5.20	5.5	2.90	0.686	0.8	56.0

①使用温度 -25~80℃ (参考値)
②ベルト周長は心線の長さです。
③特長・注意事項 P1463
④選択方法 P2462

種類 P2M (Pitch : 2mm)

Type	型式	ベルトNo.	呼び幅	歯数	ベルト周長 (mm)	¥基準単価
PTBN	80 P2M	80	80	40	80	1,040
	84 P2M	84	84	42	84	1,040
	88 P2M	88	88	44	88	1,040
	98 P2M	98	98	49	98	1,040
	100 P2M	100	100	50	100	1,040
	112 P2M	112	112	56	112	1,040
	116 P2M	116	116	58	116	1,040
	118 P2M	118	118	59	118	1,040
	124 P2M	124	124	62	124	1,060
	126 P2M	126	126	63	126	1,060
	132 P2M	132	132	66	132	1,060
	134 P2M	134	134	67	134	1,060
	136 P2M	136	136	68	136	1,060
	140 P2M	140	140	70	140	1,060
	142 P2M	142	142	71	142	1,060
	144 P2M	144	144	72	144	1,090
	146 P2M	146	146	73	146	1,090
	152 P2M	152	152	76	152	1,090
	154 P2M	154	154	77	154	1,090
	160 P2M	160	160	80	160	1,090
	162 P2M	162	162	81	162	1,090
	166 P2M	166	166	83	166	1,090
	170 P2M	170	170	85	170	1,090
172 P2M	172	172	86	172	1,090	
176 P2M	176	176	88	176	1,110	
180 P2M	180	180	90	180	1,110	
186 P2M	186	186	93	186	1,110	
190 P2M	190	190	95	190	1,110	
196 P2M	196	196	98	196	1,110	
200 P2M	200	200	100	200	1,110	
204 P2M	204	204	102	204	1,140	
208 P2M	208	208	104	208	1,140	
212 P2M	212	212	106	212	1,140	
214 P2M	214	214	107	214	1,140	
216 P2M	216	216	108	216	1,140	
220 P2M	220	220	110	220	1,140	
224 P2M	224	224	112	224	1,140	
230 P2M	230	230	115	230	1,170	

Type	型式	ベルトNo.	呼び幅	歯数	ベルト周長 (mm)	¥基準単価
PTBN	234 P2M	234	234	117	234	1,170
	236 P2M	236	236	118	236	1,170
	240 P2M	240	240	120	240	1,170
	244 P2M	244	244	122	244	1,190
	246 P2M	246	246	123	246	1,190
	250 P2M	250	250	125	250	1,190
	258 P2M	258	258	129	258	1,220
	262 P2M	262	262	131	262	1,220
	266 P2M	266	266	133	266	1,220
	270 P2M	270	270	135	270	1,220
	274 P2M	274	274	137	274	1,240
	280 P2M	280	280	140	280	1,240
	284 P2M	284	284	142	284	1,240
	290 P2M	290	290	145	290	1,270
	300 P2M	300	300	150	300	1,270
	302 P2M	302	302	151	302	1,270
	310 P2M	310	310	155	310	1,300
	318 P2M	318	318	159	318	1,300
	320 P2M	320	320	160	320	1,300
	324 P2M	324	324	162	324	1,300
	328 P2M	328	328	164	328	1,300
	330 P2M	330	330	165	330	1,300
	334 P2M	334	334	167	334	1,300
340 P2M	340	340	170	340	1,300	
348 P2M	348	348	174	348	1,300	
354 P2M	354	354	177	354	1,300	
360 P2M	360	360	180	360	1,300	
370 P2M	370	370	185	370	1,320	
378 P2M	378	378	189	378	1,350	
380 P2M	380	380	190	380	1,350	
390 P2M	390	390	195	390	1,350	
400 P2M	400	400	200	400	1,350	
408 P2M	408	408	204	408	1,370	
416 P2M	416	416	208	416	1,370	
420 P2M	420	420	210	420	1,400	
424 P2M	424	424	212	424	1,400	
426 P2M	426	426	213	426	1,430	
434 P2M	434	434	217	434	1,430	

Type	型式	ベルトNo.	呼び幅	歯数	ベルト周長 (mm)	¥基準単価
PTBN	440 P2M	440	440	220	440	1,430
	448 P2M	448	448	224	448	1,450
	464 P2M	464	464	232	464	1,480
	488 P2M	488	488	244	488	1,530
	490 P2M	490	490	245	490	1,530
	500 P2M	500	500	250	500	1,530
	516 P2M	516	516	258	516	1,530
	520 P2M	520	520	260	520	1,530
	530 P2M	530	530	265	530	1,560
	560 P2M	560	560	280	560	1,560
	576 P2M	576	576	288	576	1,570
	590 P2M	590	590	295	590	1,570
	600 P2M	600	600	300	600	1,570
	630 P2M	630	630	315	630	1,580
	638 P2M	638	638	319	638	1,580
	656 P2M	656	656	328	656	1,590
	676 P2M	676	676	338	676	1,600
	680 P2M	680	680	340	680	1,600
	704 P2M	704	704	352	704	1,620
	710 P2M	710	710	355	710	1,630
	754 P2M	754	754	377	754	1,640
	764 P2M	764	764	382	764	1,640
	774 P2M	774	774	387	774	1,640
788 P2M	788	788	394	788	1,650	
800 P2M	800	800	400	800	1,650	
808 P2M	808	808	404	808	1,650	
824 P2M	824	824	412	824	1,650	
846 P2M	846	846	423	846	1,650	
866 P2M	866	866	433	866	1,650	
898 P2M	898	898	449	898	1,660	
900 P2M	900	900	450	900	1,660	
940 P2M	940	940	470	940	1,700	
956 P2M	956	956	478	956	1,700	
992 P2M	992	992	496	992	1,700	
1040 P2M	1040	1040	520	1,040	1,710	
1242 P2M	1242	1242	641	1,242	1,800	

種類 P3M (Pitch : 3mm)

Type	型式	ベルトNo.	呼び幅	歯数	ベルト周長 (mm)	¥基準単価
PTBN	120 P3M	120	120	40	120	1,340
	123 P3M	123	123	41	123	1,340
	138 P3M	138	138	46	138	1,340
	141 P3M	141	141	47	141	1,340
	144 P3M	144	144	48	144	1,340
	147 P3M	147	147	49	147	1,340
	150 P3M	150	150	50	150	1,340
	153 P3M	153	153	51	153	1,360
	159 P3M	159	159	53	159	1,380
	162 P3M	162	162	54	162	1,380
	171 P3M	171	171	57	171	1,380
	174 P3M	174	174	58	174	1,380
	177 P3M	177	177	59	177	1,400
	183 P3M	183	183	61	183	1,400
	186 P3M	186	186	62	186	1,400
	192 P3M	192	192	64	192	1,430
	195 P3M	195	195	65	195	1,430
	198 P3M	198	198	66	198	1,430
	201 P3M	201	201	67	201	1,430
	207 P3M	207	207	69	207	1,450
	210 P3M	210	210	70	210	1,450
	213 P3M	213	213	71	213	1,470
	219 P3M	219	219	73	219	1,490
222 P3M	222	222	74	222	1,490	
225 P3M	225	225	75	225	1,510	
231 P3M	231	231	77	231	1,510	
234 P3M	234	234	78	234	1,510	
237 P3M	237	237	79	237	1,510	
240 P3M	240	240	80	240	1,510	
243 P3M	243	243	81	243	1,510	
246 P3M	246	246	82	246	1,510	
252 P3M	252	252	84	252	1,540	
255 P3M	255	255	85	255	1,540	
264 P3M	264	264	88	264	1,540	
270 P3M	270	270	90	270	1,560	
273 P3M	273	273	91	273	1,560	

Type	型式	ベルトNo.	呼び幅	歯数	ベルト周長 (mm)	¥基準単価
PTBN	276 P3M	276	276	92	276	1,560
	279 P3M	279	279	93	279	1,580
	285 P3M	285	285	95	285	1,580
	288 P3M	288	288	96	288	1,580
	291 P3M	291	291	97	291	1,580
	294 P3M	294	294	98	294	1,580
	300 P3M	300	300	100	300	1,580
	303 P3M	303	303	101	303	1,580
	306 P3M	306	306	102	306	1,580
	309 P3M	309	309	103	309	1,580
	312 P3M	312	312	104	312	1,580
	318 P3M	318	318	106	318	1,580
	330 P3M	330	330	110	330	1,600
	339 P3M	339	339	113	339	1,620
	345 P3M	345	345	115	345	1,650
	354 P3M	354	354	118	354	1,650
	360 P3M	360	360	120	360	1,650
	363 P3M	363	363	121	363	1,670
	369 P3M	369	369	123	369	1,670
	372 P3M	372	372	124	372	1,670
	384 P3M	384	384	128	384	1,690
	387 P3M	387	387	129	387	1,690
	393 P3M	393	393	131	393	1,690
399 P3M	399	399	133	399	1,690	
402 P3M	402	402	134	402	1,690	
411 P3M	411	411	137	411	1,690	
420 P3M	420	420	140	420	1,710	
423 P3M	423	423	141	423	1,760	
432 P3M	432	432	144	432	1,760	
447 P3M	447	447	149	447	1,800	
450 P3M	450	450	150	450	1,800	
453 P3M	453	453	151	453	1,800	
459 P3M	459	459	153	459	1,820	
477 P3M	477	477	159	477	1,840	
483 P3M	483	483	161	483	1,840	
486 P3M	486	486</				