

PRESS-FIT PLUNGERS

プレスフィットプランジャ/ボールボタン

-ノーマルタイプ・ローラタイプ-

BALL BUTTONS

ボールボタン

-タップタイプ-

価格改訂

パラチャージ

ステンレス・めっき品 脱脂洗浄サービス


CADデータフォルダ名: 24_Plungers

■プレスフィットプランジャ


-ノーマルタイプ-



Table with columns: Type, ボディ, ボール, スプリング, 使用可能温度. Rows include PFSSN, PFSSR, PFPSSN, PFPSPN.

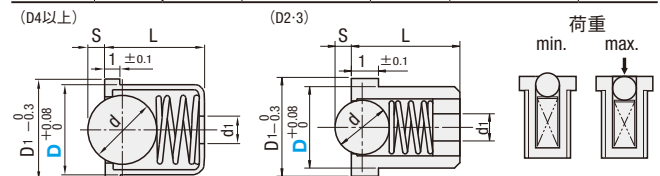

Example 使用例

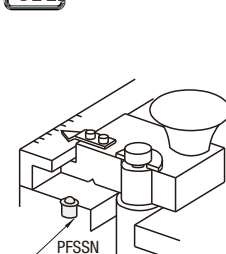

Main specification table for normal type plungers with columns for Type, D, D1, L, S, d, d1, and load capacity (PFSSN, PFSSR, PFPSSN, PFPSPN).

取付穴推奨寸法 D+0.013, 抜け防止には接着剤をあわせてお使いください.

Order and delivery information for normal type plungers, including PFSSN4 and delivery options.

Price and quantity information for normal type plungers, including quantity slide prices and delivery options.


Additional specifications and notes for normal type plungers, including PFSSN以外 and quantity information.

■プレスフィットプランジャ


-ローラタイプ-



Table with columns: Type, ボディ, メインボール, サブボール, スプリング, 使用可能温度. Row includes PFPR.

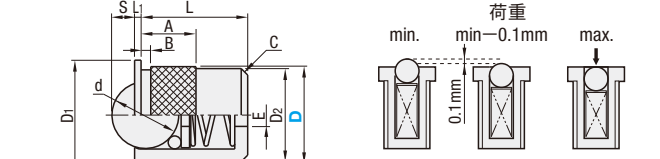

■特長

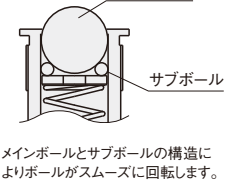

Main specification table for roller type plungers with columns for Type, D, D1, D2, L, S, L1, d, A, B, E, C, and load capacity.

取付穴推奨寸法 Dns

Order and delivery information for roller type plungers, including PFPR15 and delivery options.

Price and quantity information for roller type plungers, including quantity slide prices and delivery options.


Additional specifications and notes for roller type plungers, including quantity information.

■ボールボタン


-タップタイプ-



Table with columns: Type, 材質, 硬度, 表面処理. Row includes TBBT.

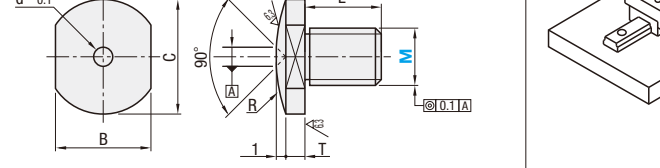

Example 使用例

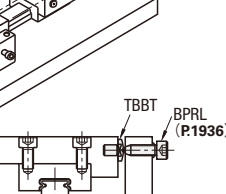

Main specification table for tap type ball buttons with columns for Type, M (並目), B, L, C, T, R, d, and load capacity.

取付穴推奨寸法 Dns

Order and delivery information for tap type ball buttons, including TBBT6 and delivery options.

Price and quantity information for tap type ball buttons, including quantity slide prices and delivery options.

Additional specifications and notes for tap type ball buttons, including quantity information.

ROLLER PLUNGERS

ローラプランジャ

-コンパクトタイプ・マウントタイプ・ボルトタイプ-

CADデータフォルダ名: 24_Plungers


■特長: 先端部にベアリングのついたプランジャです。

■コンパクトタイプ

-荷重調整機能付-



Table with columns: Type, ①②③本体・アーム調整用なし, ④ベアリング, ⑤ベアリング軸, ⑥スプリング, ⑦止めねじ, ⑧ナット. Row includes CBPJ.

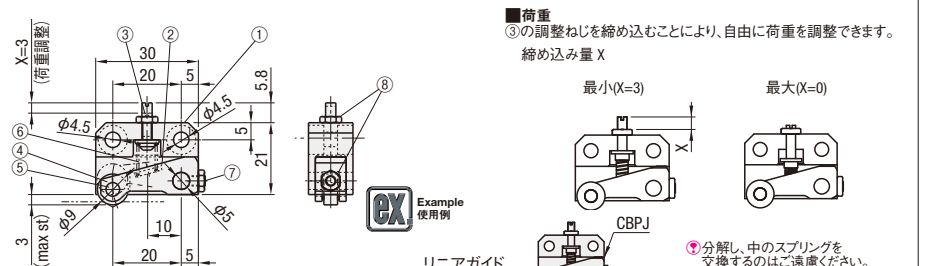

荷重調整機能: ③の調整ねじを締め込むことにより、自由に荷重を調整できます。最小(X=3) 最大(X=0)

Main specification table for compact type plungers with columns for Type, No., 最小締め込み時(X=3), 最大締め込み時(X=0), and load capacity.


取付穴推奨寸法 D+0.013

Order and delivery information for compact type plungers, including CBPJ9 and delivery options.

Price and quantity information for compact type plungers, including quantity slide prices and delivery options.

■マウントタイプ

Table with columns: Type, 本体, ピン, ベアリング, プッシュ, スプリング. Rows include TBPJ, SBPJ.

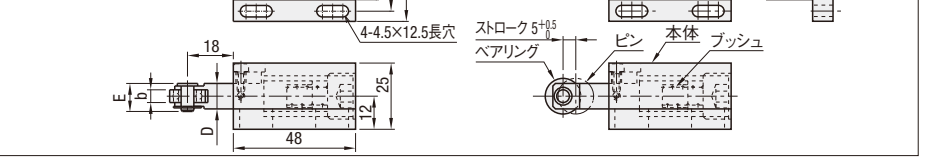

Main specification table for mount type plungers with columns for Type, No., d, b, D, E, L1, 荷重(N), and load capacity.


No.1A・2Aのタイプは従来品よりもベアリング径が大きくなっています。

Order and delivery information for mount type plungers, including TBPJ2A and delivery options.

Price and quantity information for mount type plungers, including quantity slide prices and delivery options.

■ボルトタイプ

Table with columns: Type, 本体, ピン, ベアリング, プッシュ, スプリング, 付属品(ナット2コ). Rows include RBPJ, RBSJ.

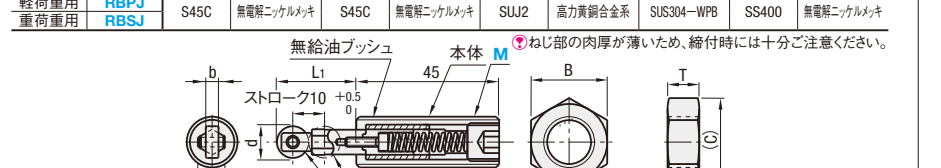

Main specification table for bolt type plungers with columns for Type, M (並目), d, b, E, L1, M (並目), B, T, 荷重(N), and load capacity.

取付穴推奨寸法 Dns

Order and delivery information for bolt type plungers, including RBPJ20 and delivery options.

Price and quantity information for bolt type plungers, including quantity slide prices and delivery options.

24 プランジャ