

RIBS -LIGHTENED TYPE-


リブ

—軽量化タイプ—



◎カタログ規格外品はこちら P.137 ◎CADデータフォルダ名: 32_Ribs_and_Angle_Plates

■特長: 軽量化タイプのリブです。従来品(P.2399)と比べ、最大35%の軽量化を実現しました。

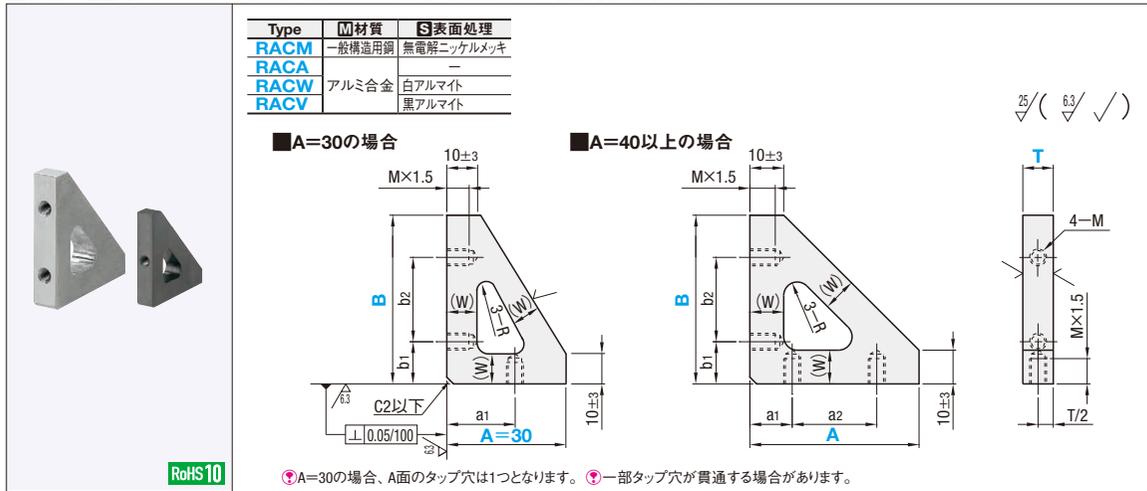

RoHS 10

◎A=30の場合、A面のタップ穴は1つとなります。◎一部タップ穴が貫通する場合があります。

型式 Type	A	B	T選択		M	A面ピッチ		B面ピッチ		肉抜き (W) R	重量 (g:参考値)	¥基準単価					
			一般構造用鋼	アルミ合金		a1	a2	b1	b2			一般構造用鋼	アルミ合金	RACM	RACA	RACW	RACV
(一般構造用鋼) RACM	30	30	6	6	3	20	—	10	*10	6	4	27.5	9.8	1,940	1,330	1,450	1,590
			12	12	6							55.0	19.6	2,090	1,400	1,470	1,610
		9	10	5	49.4							20.1	2,190	1,460	1,520	1,670	
		12	12	6	67.5							24.1	2,220	1,470	1,560	1,710	
		9	10	5	58.5							23.9	2,410	1,590	1,680	1,840	
		12	12	6	80.3							28.7	2,500	1,630	1,660	1,820	
	40	40	9	10	5	15	15	15	20	8	4	68.4	28.0	2,520	1,650	1,690	1,850
			12	12	6							94.0	33.6	2,580	1,660	1,730	1,900
		9	10	5	88.1							36.2	2,700	1,740	1,900	2,090	
		12	12	6	121.4							43.4	2,760	1,750	1,950	2,140	
		9	10	5	67.7							27.3	2,200	1,460	1,520	1,670	
		12	12	6	91.8							32.8	2,310	1,500	1,560	1,710	
(アルミ合金) RACA RACW RACV	50	50	9	10	5	12.5	25	20	40	10	4	101.4	40.8	2,560	1,650	1,740	2,010
			12	12	6							113.6	46.0	2,600	1,650	1,740	2,010
		9	10	5	139.8							57.1	2,760	1,720	1,790	2,060	
		12	12	6	191.6							68.5	2,930	1,770	1,870	2,150	
		9	10	5	166.7							68.4	3,060	1,870	1,940	2,240	
		12	12	8	229.4							82.0	3,310	1,960	1,980	2,280	
	60	60	9	10	5	15	30	15	30	10	4	125.8	51.4	2,730	1,710	1,910	2,100
			12	12	6							172.5	61.7	2,870	1,750	1,950	2,140
		9	10	5	150.7							62.3	2,990	1,830	2,010	2,210	
		12	12	6	208.8							74.8	3,160	1,870	2,050	2,250	
		9	10	5	176.2							73.4	3,270	1,960	2,290	2,510	
		12	12	8	245.8							88.1	3,510	2,020	2,350	2,580	
80	80	9	10	5	20	40	20	40	12	5	202.3	83.2	3,040	1,960	2,170	2,500	
		12	12	6							279.0	99.8	3,480	2,000	2,220	2,560	
	9	10	5	231.6							96.3	3,800	2,240	2,390	2,760		
	12	12	8	322.5							115.6	4,100	2,310	2,450	2,820		
	9	10	5	307.3							129.9	4,320	2,420	2,530	2,920		
	12	12	8	434.0							155.9	4,830	2,590	2,680	3,100		
100	100	9	10	5	25	50	25	50	15	6	309.7	127.1	4,130	2,380	2,500	2,890	
		12	12	8							426.3	152.5	4,440	2,460	2,560	2,950	
	9	10	5	398.2							166.8	4,860	2,680	2,740	3,160		
	12	12	8	557.7							200.1	5,020	2,800	2,850	3,280		

◎一部タップ穴が貫通する場合があります。*の製作公差は ± 0.2 です。その他の寸法は一般公差(JISB0405)です。



Order 注文例
型式 - B - T
RACM40 - 60 - 9
RACA40 - 60 - 10



Delivery 出荷日
3 日日出荷



Price 価格

■数量スライド価格 (◎1円未満切り捨て) P.133

数量区分	標準対応			個別対応
	小口	大口	大口	
数量	1~9	10~15	16~19	20~30
値引率	標準単価	5%	10%	18%
出荷日	通常	通常	+3日	お見積り

◎表示数量超えはWOSIにてご確認ください。

RIBS -BRIDGE TYPE-


リブ

—ブリッジタイプ—



◎カタログ規格外品はこちら P.137 ◎CADデータフォルダ名: 32_Ribs_and_Angle_Plates

■特長: ブリッジ形状の為、配線など干渉物がある際にもご利用頂けます。(使用例参照)

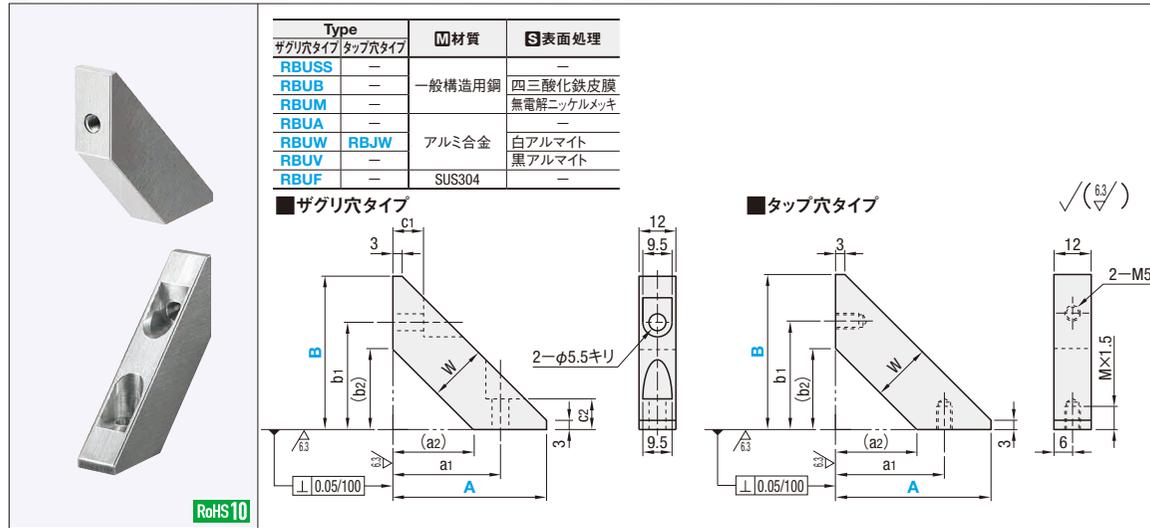

RoHS 10

型式 Type	A	B	a1	b1	(a2)	(b2)	c1	c2	W
(一般構造用鋼) RBUSS RBUB RBUM	50	50	40	40	26.1	26.1	5	5	19
		80	40	60	29.5	48.4	10	10	
		100	40	80	30.3	62.6	5	5	
(アルミ合金) RBUA RBWU RBVU RBUF	80	80	65	65	51.8	51.8	10	10	22
		100	65	80	54.2	68.3	10	10	
		150	85	85	71.8	71.8	10	10	



Order 注文例
型式 - B
RBUF100 - 150
RBWU50 - 80



Delivery 出荷日
3 日日出荷




Price 価格

■数量スライド価格 (◎1円未満切り捨て) P.133

数量区分	標準対応			個別対応
	小口	大口	大口	
数量	1~9	10~15	16~19	20~30
値引率	標準単価	5%	10%	18%
出荷日	通常	通常	+3日	お見積り

◎表示数量超えはWOSIにてご確認ください。

A	B	¥基準単価							
		Zaguri穴						タップ穴	
		RBUSS	RBUB	RBUM	RBUA	RBWU	RBVU	RBUF	RBWU
50	50	2,480	2,580	2,660	1,420	1,610	1,890	3,400	1,510
	80	2,600	2,830	2,990	1,490	1,700	1,990	3,580	1,600
	100	2,750	3,040	3,250	1,570	1,770	2,040	3,790	1,670
80	80	2,970	3,310	3,580	1,690	1,980	2,380	4,090	1,880
	100	3,360	3,800	4,120	1,910	2,190	2,580	4,630	2,090
100	100	3,890	4,410	4,790	2,200	2,480	2,870	5,360	2,380
	150	4,280	5,020	5,240	2,420	2,710	3,110	5,910	2,610

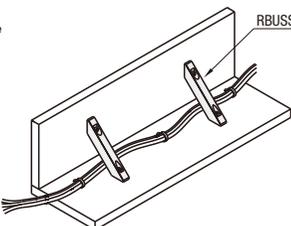

■配線が干渉することなく、取付けることが可能です。

32 リブ・イケール
溶接スタンド下