




SS400 DIMENSION FIXED PLATES -6 SURFACE MILLING(ECONOMY) / MILLING & UPPER-LOWER SURFACE ROTARY GRINDING(STANDARD)-

# SS400寸法固定プレート

-6面フライス/側面フライス+板厚面ロータリー研磨-

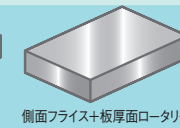

材料屋24でミスミ型番・出荷日・価格を一発表示!

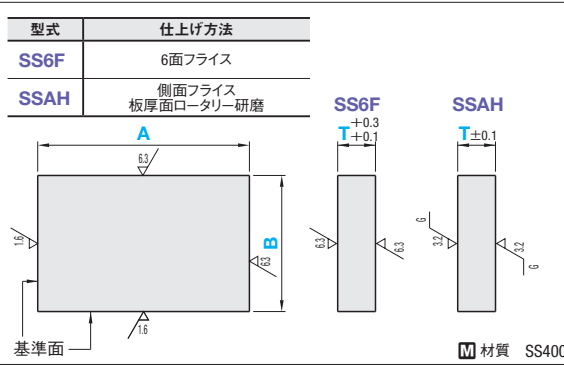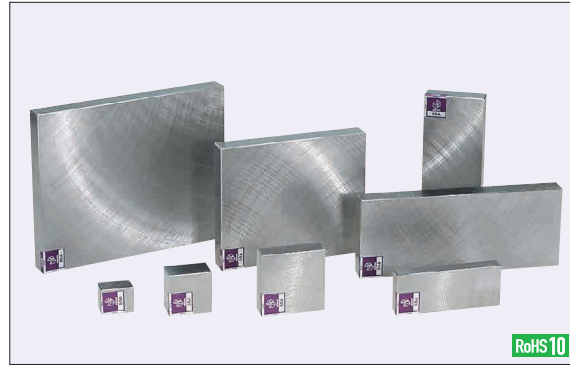

型式	仕上方法	A・B寸法公差			板厚平行度 (100mmあたり)	平面度 (100mmあたり)				基準面直角度 (100mmあたり)	全周面取り
		~99mm	100~250	251~		~T6	T8~15	T16~25	T28~		
SS6F	6面フライス				0.05	0.1	0.07	0.05	0.05		C0.2~C0.5
SSAH	側面フライス 板厚面ロータリー研磨	±0.2mm	±0.25	±0.4	0.012	0.05	0.03	0.015	0.012	0.015	C0.5~C1.0

### 6面フライス

型式	A	T	B	寸法																		
				5	6	8	9	10	12	13	15	16	19	20	22	25	28	30	34	35	40	50
SS6F	60	60																				
	80	80																				
	100	100																				
	125	125																				
	150	150																				
	160	160																				
	200	200																				
	250	250																				
	300	300																				
	350	350																				
	400	400																				
	450	450																				
	500	500																				
	200	200																				
	250	250																				
300	300																					
350	350																					
400	400																					
450	450																					
500	500																					
200	200																					
250	250																					
300	300																					
350	350																					
400	400																					
450	450																					
500	500																					
200	200																					
250	250																					
300	300																					
350	350																					
400	400																					
450	450																					
500	500																					

Web 金額はWOSにてご確認ください。

Order 注文例

型式	A	B	T
SS6F	100	100	8
SSAH	100	100	8

Delivery 出荷日

型式	目目出荷	注文締切	納期
SS6F A (長さ) 300mm以下	1	当日出荷	800円/1本
SS6F A (長さ) 350mm以上	3	当日出荷	800円/1本
SSAH	3	翌日出荷	800円/1本

①1日目の受付けは17時までです。それ以降のご注文は翌営業日扱いとなります。

②3本以上で1明細行当たり一律2,160円

③11個以上は納期が変わる可能性があります。

④21個以上は納期が変わる可能性があります。

Price 価格 WOSにてご確認ください。

### 側面フライス+板厚面ロータリー研磨

型式	A	T	B	寸法																		
				5・6	8・9	10	12・13	15・16	19・20	22	25	28	30	34・35	40	50						
SSAH	60	60																				
	80	80																				
	100	100																				
	125	125																				
	150	150																				
	160	160																				
	200	200																				
	250	250																				
	300	300																				
	350	350																				
	400	400																				
	450	450																				
	500	500																				
	200	200																				
	250	250																				
300	300																					
350	350																					
400	400																					
450	450																					
500	500																					
200	200																					
250	250																					
300	300																					
350	350																					
400	400																					
450	450																					
500	500																					

Web 金額はWOSにてご確認ください。