


S50C DIMENSION FIXED PLATES -6 SURFACE MILLING(ECONOMY) / MILLING & UPPER-LOWER SURFACE ROTARY GRINDING(STANDARD)-

S50C寸法固定プレート

-6面フライス/側面フライス+板厚面ロータリー研磨-



材料屋24でミス型番・出荷日・価格を一発表示!

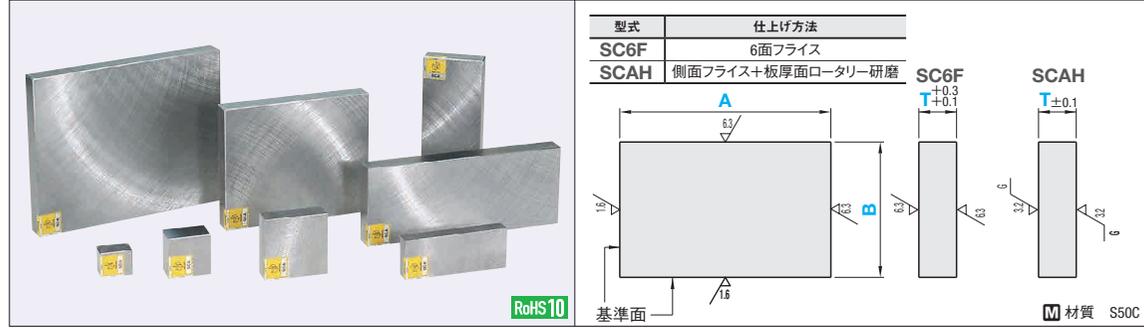

型式	仕上方法	A・B寸法公差			板厚平行度 (100mmあたり)	平面度(100mmあたり)				基準面直角度 (100mmあたり)	全周面取り
		~99mm	100~250	251~		~T6	T8~15	T16~25	T28~		
SC6F	6面フライス	±0.2mm	±0.25	±0.4	0.05	0.1	0.07	0.05	0.05	0.015	C0.2~C0.5
SCAH	側面フライス 板厚面ロータリー研磨					0.05	0.03	0.015	0.012		

■6面フライス		A	B	T	5	6	8	9	10	12	13	15	16	19	20	22	25	28	30	34	35	40	50			
SC6F	60	60																								
		80																								
		100																								
		125																								
		150																								
	80	160																								
		200																								
		250																								
		300																								
		500																								
	100	100																								
		125																								
		150																								
		160																								
		200																								
	125	250																								
		300																								
		350																								
		400																								
		500																								
150	100																									
	125																									
	150																									
	160																									
	200																									
160	250																									
	300																									
	350																									
	400																									
	500																									
200	200																									
	250																									
	300																									
	350																									
	500																									
250	250																									
	300																									
	350																									
	400																									
	500																									
300	300																									
	350																									
	400																									
	450																									
	500																									

Web 金額はWOSにてご確認ください。

Order 注文例

型式 - A - B - T
 SC6F - 100 - 100 - 8
 SCAH - 100 - 100 - 8

Delivery 出荷日

- SC6F A(長さ) 300mm以下
 - 1 日日出荷 (1個以上) ストック T 当日出荷 800円/1本 正午迄 注文 P.134
 - 3 日日出荷 (1個以上) ストック T 当日出荷 800円/1本 正午迄 注文 P.134
- SC6F A(長さ) 350mm以上
 - 3 日日出荷 (1個以上) ストック T 翌日出荷 800円/1本 PM 6:00迄 注文 P.134
- SCAH
 - 3 日日出荷 (1個以上) ストック A 翌日出荷 800円/1本 PM 6:00迄 注文 P.134

①1日出荷の受付はPM5:00までです。それ以降のご注文は翌営業日扱いとなります。

②3本以上で1明細行当たり一律2,160円

③21個以上は納期が変わる可能性があります。

Price 価格 WOSにてご確認ください。

■側面フライス+板厚面ロータリー研磨		A	B	T	5・6	8・9	10	12・13	15・16	19・20	22	25	28	30	34・35	40	50		
SCAH	60	60																	
		80																	
		100																	
		125																	
		150																	
	80	160																	
		200																	
		250																	
		300																	
		500																	
	100	100																	
		125																	
		150																	
		160																	
		200																	
	125	250																	
		300																	
		350																	
		400																	
		500																	
150	100																		
	125																		
	150																		
	160																		
	200																		
160	250																		
	300																		
	350																		
	400																		
	500																		
200	200																		
	250																		
	300																		
	350																		
	500																		
250	250																		
	300																		
	350																		
	400																		
	500																		
300	300																		
	350																		
	400																		
	450																		
	500																		

Web 金額はWOSにてご確認ください。