

快削真鍮 フラットバー 平角棒・四角棒

強度が高く、展延性に優れます。




Delivery
出荷日

3 日目発送

型式例

材質記号 - 管理記号 - 母材規格 - A(長さ) - B(幅) - T(板厚)
C3604 - FBH - 10×50 - 100 - 50 - 10

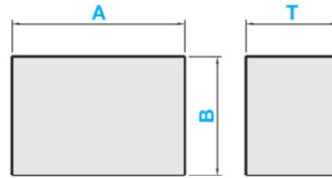

■寸法公差

長さ寸法公差	0~+2	
板厚・幅寸法公差		
板厚	板厚公差	幅公差
3	±0.08	±0.8
4~5	±0.1	幅×±1%
6~8	±0.13	
9~12	±0.18	
13~20	±0.23	
22以上	板厚×±1.3%	

平角棒

板厚 × 幅	長さ 指定1mm単位	
3 × 10	15	
	20	
	25	
	30	
	35	
	38	
	40	
	50	
	4 × 10	15
		16
20		
25		
30		
35		
40		
50		
5 × 10		12
		15
	16	
	18	
	19	
	20	
	22	
	25	
	30	
	32	
	35	
	40	
	45	
	50	
	60	
6 × 10	12	
	13	
	14	
	15	
	16	
	18	
	19	
	20	
	22	
	25	
	30	
	32	
	35	
	38	
	40	
	45	
	50	
	60	
	65	

板厚 × 幅	長さ 指定1mm単位
8 × 10	12
	14
	15
	16
	18
	20
	22
	25
	30
	32
9 × 12	15
	18
	20
	25
	30
	35
	38
	40
	50
	100
10 × 12	15
	16
	18
	20
	22
	25
	30
	32
	35
	38
	40
	45
	50
	60
	75
100	
12 × 15	16
	18
	20
	22
	25
	30
	32
	35
	38
	40
	45
	50
	60
	75
	100

板厚 × 幅	長さ 指定1mm単位	
15 × 18	20	
	25	
	30	
	32	
	35	
	40	
	45	
	50	
	60	
	80	
16 × 20	25	
	30	
	30	
	35	
	40	
20 × 25	30	
	35	
	40	
	45	
	50	
	60	
	75	
	30~2000	
	25 × 30	35
		40
45		
50		
60		
30 × 35	40	
	45	
	50	
	60	
	75	
35 × 40	50	
	60	
	75	
	80	
	60	
40 × 80	60	
	80	
	60	

四角棒

板厚×幅	長さ 指定1mm単位
10×10	30~2000
11×11	
12×12	
13×13	
14×14	
15×15	
16×16	
17×17	
18×18	
19×19	
20×20	
22×22	
24×24	
25×25	
28×28	
30×30	
32×32	
35×35	
36×36	
38×38	
40×40	
42×42	
45×45	
50×50	
55×55	
60×60	
65×65	
70×70	
75×75	
80×80	
90×90	
100×100	



業界トップクラスのサイズバリエーション!
欲しいサイズを1個から、自慢の価格でご提供いたします。