



Delivery
出荷日



1※ 日目発送

※ミスミ稼働日の土曜・祝日を除き1日目出荷。土曜・祝日のご注文は翌営業日扱いとなります。平日12時以降のご注文は翌営業日扱いとなります。

型式例

材質記号	管理記号	母材規格	A(長さ)	B(幅)	T(板厚)
SUS316	FBH	10×50	100	50	10
材質記号	管理記号	母材規格	A(長さ)	B(幅)	T(板厚)
SUS316L	FBH	10×50	100	50	10

①51個以上は出荷日が異なる場合があります。

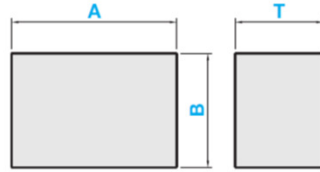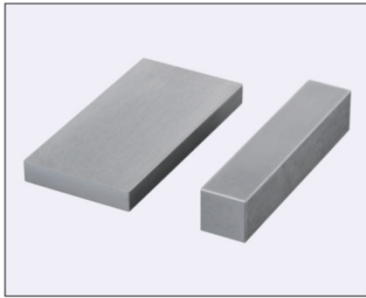

■寸法公差
長さ寸法公差

30~999	0~+1
1000~2000	0~+2

板厚・幅寸法公差

板厚	公差	幅					
		~50	51~75	76~99	100~125	126~150	151~200
~20	板厚	±0.4	±0.5	±0.5	±0.5	±0.5	±0.6
	幅	±0.8	±1.0	±1.2	±2.0	±2.5	±2.5
21~36	板厚	±0.5	±0.5	±0.5	±0.6	±0.6	±0.6
	幅	±0.8	±1.0	±1.2	±2.0	±2.5	±2.5
37~40	板厚	—	±0.5	±0.7	±0.6	±0.6	±0.6
	幅	—	±1.0	±0.8	±2.0	±2.5	±2.5
41~50	板厚	—	±1.5	±0.7	±0.6	±0.6	±0.6
	幅	—	±1.2	±0.8	±2.0	±2.5	±2.5
51~150	板厚	—	±1.5	±0.7	±0.6	±0.6	±0.6
	幅	—	±1.2	±0.8	±2.0	±2.5	±2.5

②四角棒は板厚公差をご参照下さい。

平角棒

SUS303

板厚	×	幅	長さ 指定1mm単位
6	×	25	30~2000
		30	
		40	
		50	
		65	
		75	
		100	
9	×	25	
		30	
		40	
		50	
		65	
		75	
		100	
12	×	25	
		30	
		40	
		50	
		65	
		75	
		100	
		150	
		200	
16	×	25	
		30	
		40	
		50	
		65	
		75	
		100	
		150	
		200	
19	×	25	
		30	
		40	
		50	
		65	
		75	
		100	
		150	
		200	
22	×	25	
		30	
		40	
		50	
		65	
		75	
		100	
		150	
		200	
25	×	50	
		65	
		75	
		100	
		150	
		200	
30	×	50	
		75	
		100	
		150	
		200	
35	×	50	
		75	
		100	
40	×	50	
		75	
		100	
50	×	75	
		100	

SUS316・316L

板厚	×	幅	長さ 指定1mm単位
3	×	20	30~2000
		25	
		30	
		32	
		38	
		40	
		50	
4	×	25	
		30	
		40	
		50	
5	×	20	
		25	
		30	
		38	
		40	
		50	
6	×	25	
		30	
		32	
		38	
		40	
		50	
		65	
		75	
		100	
9	×	25	
		30	
		32	
		38	
		50	
		65	
		75	
		100	
10	×	50	
		100	
12	×	25	
		32	
		38	
		50	
		65	
		75	
		100	
16	×	32	
		38	
		50	
		65	
		75	
		100	
19	×	50	
		65	
		75	
		100	

四角棒

SUS303

板厚	×	幅	長さ 指定1mm単位
16	×	16	30~2000
19	×	19	
22	×	22	
25	×	25	
30	×	30	
32	×	32	
36	×	36	
40	×	40	
45	×	45	
50	×	50	
60	×	60	
65	×	65	
75	×	75	
90	×	90	
100	×	100	

SUS316・316L

板厚	×	幅	長さ 指定1mm単位
19	×	19	30~2000
20	×	20	
22	×	22	
25	×	25	
30	×	30	
32	×	32	
38	×	38	
42	×	42	
50	×	50	