




Delivery
出荷日

3 日目発送

 
型式は寸法や数量により異なります。
 材料屋24サイトで都度お見積り下さい。
 20個以上は出荷日が異なる場合があります。

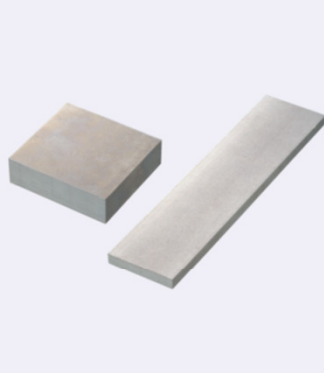

平鋼



四角材



■寸法公差

板厚(T)寸法公差

5~6	8~10	12~16	19~30	40~50
0	0	0	0	0
-0.18	-0.22	-0.27	-0.30	-0.39

幅(B)寸法公差

16	~25	~50	~60	~100	~125
0	0	0	0	0	0
-0.18	-0.21	-0.25	-0.30	-0.35	-0.40

平角棒

四角棒

■SS400D (C)

板厚 × 幅	長さ 指定1mm単位	板厚 × 幅	長さ 指定1mm単位	板厚 × 幅	長さ 指定1mm単位
3 × 25		12 × 20		22 × 90	
32		22		100	
38		25		125	
50		32		150	
5 × 32		38		180	
38		44		200	
44		45		250	
50		50		300	
6 × 32		60		350	
38		65		400	
40		75		450	
44		90		500	
45		100		25 × 32	
50		125		38	
60		150		44	
65		180		45	
75		200		50	
90		250		60	
100		300		65	
125		350		75	
150		400		90	
180		450		100	
200		500		125	
250		16 × 19		150	
300		20		180	
350		22		200	
400		25		250	
9 × 12		32		300	
13		38		350	
16		44		400	
19		45		450	
22		50		500	
25		60		30 × 50	
32		65		65	
38		75		75	
44		90		100	
45		100		125	
50		125		150	
60	10~2000	150	10~2000	200	10~2000
65		180		250	
75		200		300	
90		250		350	
100		300		400	
125		350		450	
150		400		32 × 50	
180		450		65	
200		500		75	
250		19 × 22		100	
300		25		125	
350		32		150	
400		38		200	
450		44		32 × 50	
500		45		75	
10 × 12		50		100	
13		60		125	
15		65		150	
16		75		200	
20		90		38 × 50	
22		100		65	
25		125		75	
30		150		100	
32		180		125	
38		200		150	
40		250		200	
50		300		16 × 19	
60		350		22	
65		400		25	
75		450		32	
90		500		38	
100		22 × 25		44	
125		32		50	
150		38		60	
200		44		75	
250		50		90	
300		60		100	
12 × 16		65		125	
19		75		150	
				200	

■S45CD (C)

板厚 × 幅	長さ 指定1mm単位	板厚 × 幅	長さ 指定1mm単位
3 × 25		19 × 50	
32		60	
38		65	
50		75	
5 × 32		90	
6 × 32		100	
38		125	
44		150	
50		200	
60		250	
65		300	
75		22 × 25	
90		32	
100		38	
125		44	
150		50	
200		60	
250		65	
300		75	
9 × 13		90	
16		100	
19		125	
22		150	
25		200	
32		250	
38		300	
44		30 × 50	
50		65	
60		75	
65		100	
75		125	
90		150	
100		200	
125		10 × 32	
150		38	
180		50	
200		100	
250		12 × 16	
300		32	
350		38	
400		44	
450		50	
500		60	
10 × 12		65	
13		75	
15		90	
16		100	
20		125	
22		150	
25		200	
30		16 × 19	
32		22	
38		25	
40		32	
50		38	
60		44	
65		50	
75		60	
90		75	
100		90	
125		100	
150		125	
200		150	
250		300	
300		19 × 22	
350		25	
400		32	
450		38	
500		44	

■SS400D (C)

板厚×幅	長さ 指定1mm単位
20×20	
22×22	
25×25	
26×26	
28×28	
30×30	
32×32	
35×35	
36×36	
38×38	
40×40	
42×42	
44×44	10~2000
45×45	
46×46	
50×50	
55×55	
60×60	
65×65	
70×70	
75×75	
80×80	
85×85	
90×90	
100×100	

■S45CD (C)

板厚×幅	長さ 指定1mm単位
20×20	
22×22	
25×25	
26×26	
28×28	
30×30	
32×32	
35×35	
38×38	
40×40	
42×42	
44×44	10~2000
45×45	
50×50	
55×55	
60×60	
65×65	
70×70	
75×75	
80×80	
85×85	
90×90	
100×100	